



Why Corning Glass? Superior Hole Quality

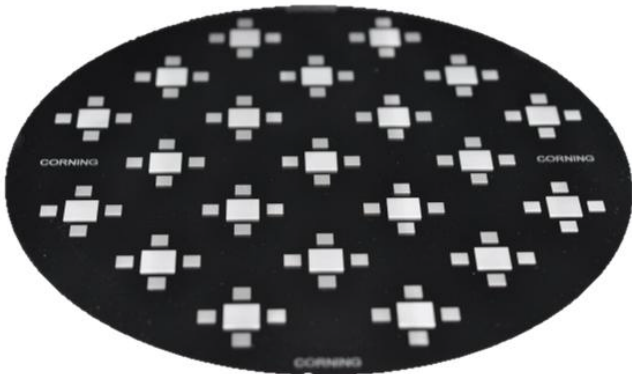


Fully patterned wafer with 100,000s of holes


Wafer Size:	100mm → 300mm
Panel Size:	>500 x 500mm
Thickness:	~100μm → 700μm
Type of Holes:	Blind-Holes, Thru-Holes
Pattern:	Customer X,Y Location
Aspect Ratio:	~3–10:1
Pitch:	Minimum 2 x Hole Diameter
Hole Diameter:	100μm → 20μm

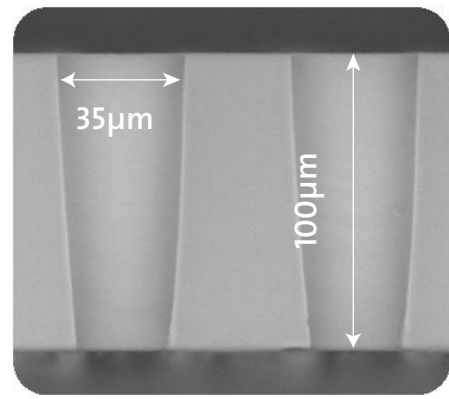


Thru-Holes on thin glass

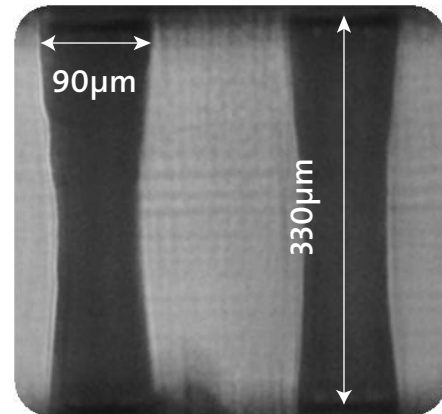


Thru-Holes on thick glass

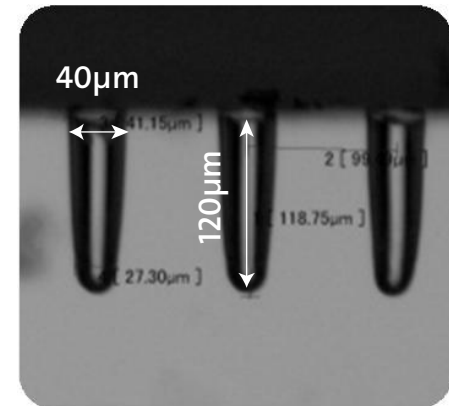

Blind-holes 120μm deep

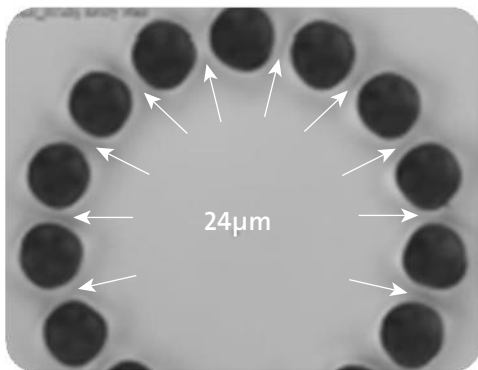

Space edge to edge 24μm

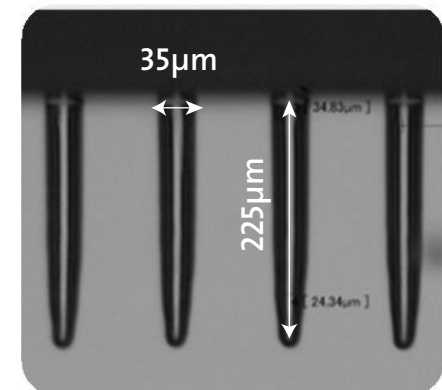

Blind-holes 225μm deep

Regional Sales Office

China

Corning China (Shanghai) Regional Headquarters
6F, Li Ming Building, 111 Gui Qing Road
Shanghai, 200233, China
Phone: 0086 21 3338 4338 | Fax: 0086 21 3338 4300

Europe

Corning GmbH - Corning International
Abraham-Lincoln Strasse 30
Wiesbaden, Germany
Phone: +49 611 7366 101 Fax: +49 611 7366 143

Japan

Corning International K.K.
Akasaka Intercity 7th floor
1-11-44 Akasaka, Minato-ku
Tokyo, 107-0052, Japan
Phone: +81 3 3586 5002 | Fax: +81 3 3224 1405

Korea

Corning Korea Company, Ltd.
6th Fl., Gangnam Finance Center
737 Yeoksam-Dong, Gangnam-Gu,
Seoul, 140-702, Korea
Phone: 82 2 796 9500 | Fax: 82 2 796 9300

North America

Corning Incorporated
MP-HQ-W1
Corning, NY 14831
United States
Phone: +607 974 9000

Singapore

Corning Singapore Holdings Pet Ltd.
1, Kim Seng Promenade
Great World City
#9-11/12 West Tower
237994, Singapore
Phone: +65-65729740 | Fax: +65-67352913

Taiwan

Corning Incorporated- Taiwan
8F., No.8, Sec.3, Minsheng E. Rd.
Zhongshan Dist., Taipei City 10480
Taiwan, R.O.C.
Phone: +886 2 2716 0338

CORNING

To place an order, obtain additional technical information or specific requirements please contact semiglass@corning.com or one of our regional sales offices.

To learn more, visit us at www.corning.com/semiglass.